


Naziv PDF datoteke

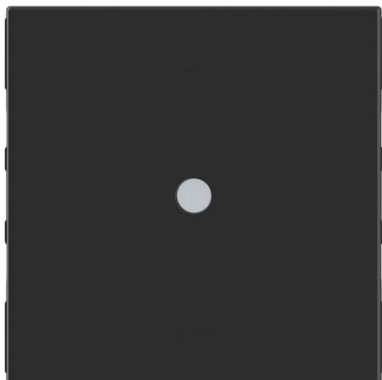

CLASSIA BTICINO

Connected switch with neutral (with dimmer option)
150W Classia with Netatmo

REF. BT-RG4412CM2 | EAN KODA. 8005543674079

> [The product details page](#)

Značilnosti izdelka:

- Max load power : 150W under 230V~, all loads leds included
- Compatible with traditional or dimmable bulbs, including LED. Dimmer activatable via Home + Control App
- LED indicator with locator function which can be activated in the app
- Equipped with an auxiliary entry for a mechanical push button
- Radio technology 2.4GHz, using Zigbee 3.0 protocol, reliable and secure

Priporočila / omejitve

- To connect your connected switch with neutral (with dimmer option), it is necessary to purchase and install a Classia with Netatmo connected starter pack beforehand. To control it as a 2 way switch, it is necessary to associate one or more Classia with Netatmo wireless commands to it and / or wire it with a mechanical push button.

Prednosti montaže:

- The Classia with Netatmo connected switch with neutral (with dimmer option) is easily installed in place of an existing switch and requires a standard depth flush mounting box (40mm). Compatible with claw frames. Does not require the installation of a bleeder

Prednosti uporabe:

- Control your lights with your voice using a vocal assistant

Edinstvene značilnosti:

- Perfect aesthetic integration with the installed wiring devices
- Using ON/OFF mode, compatible with all type of loads, dimmable or not
- Very easy to use with multi-zone ergonomics

Dokumentacija

Tehnična dokumentacija



LE12181AD.pdf | PDF (1.62Mo)



IDP000352_01-EN.pdf | PDF (1.08Mo)

Pogodbe in certifikati



OC / CB-DE 2-0310068 | (0.66Mo)