


Naziv PDF datoteke

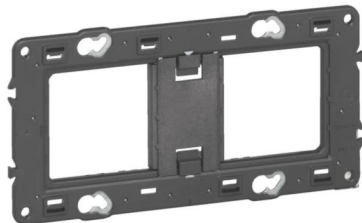

MOSAIC™ LEGRAND

Mosaic™ - Support - with site protection - for 4, 5 or 2 x 2 horizontal/vert. mod.

REF. 080252 | EAN KODA. 3245060802523

> [The product details page](#)

Značilnosti izdelka:

- supports with site protection - For 4, 5 or 2 x 2 modules , horizontal or vertical

Dokumentacija

Tehnična dokumentacija

 F00440FR-02.pdf | PDF (0.66Mo)

 F00440EN-02.pdf | PDF (0.66Mo)

CAD & specifikacije načrtov / BIM

BIM-LEGRAND-CELIANE-2025-FRANCAIS.rvt | RVT (169.55Mo)

 3D_LG-080252.stp | IFC (6.09Mo)

BIM-LEGRAND-MOSAIC-2025-FRANCAIS.rvt | RVT (124.38Mo)

BIM-LEGRAND-MOSAIC-2025-ENGLISH.rvt | RVT (125.73Mo)

Katalog & drugo

 ex223001_1204.pdf | PDF (0.18Mo)

Pogodbe in certifikati

 NF App Domestic-NF012_4571/M1 | (1Mo)

 OC / CB-FR_700177/A1 | (0.71Mo)

 B.B.J-B/12/006/24 | (3.34Mo)

 B.B.J-B/12/048/21 | (2.83Mo)

 NF App Domestic-NF012_4236 | (0.53Mo)

 LGRP-00046-V01.01-FR.pdf | PDF (0.74Mo)

 OC / CB-FR_707532/M1 | (1.51Mo)

 OC / CB-FR 630163B/A1 | (0.56Mo)

 LGRP-01211-V01.01-EN.pdf | PDF (0.71Mo)

 LGRP-00045-V01.01-FR.pdf | PDF (0.75Mo)

 OC / CB-620080 | (2.41Mo)

 OC / CB-FR_709693/M1 | (0.67Mo)

 OC / CB-FR_708376 | (1.33Mo)

 LGRP-01197-V01.01-FR.pdf | PDF (0.77Mo)

 OC / CB-FR_707308/A3 | (4.23Mo)

 MEEI-UP 69267544 001 | (2.21Mo)

	OC / CB-FR_720392 (0.4Mo)
	OC / CB-HU-005377 (0.56Mo)
	OC / CB-FR_709181 (0.68Mo)
	NF App Domestic-NF012_1945 (0.74Mo)
	OC / CB-HU-005009-A1/M1 (0.73Mo)
	LGRP-00991-V01.01-FR.pdf PDF (0.71Mo)
	NF App Domestic-NF012_2201/A2 (1.3Mo)
	OC / CB-FR_719966 (0.38Mo)
	MEEI-UP 69258630 0001 (0.23Mo)
	NF App Domestic-NF012_2513 (1.2Mo)
	LGRP-00942-V02.01-FR.pdf PDF (0.86Mo)
	LGRP-01120-V01.01-EN.pdf PDF (0.68Mo)
	B.B.J-B/12/047/21 (2.9Mo)
	AENOR-030/002285 (0.47Mo)
	OC / CB-FR_709703 (1.06Mo)
	NF App Domestic-NF012_2666/M1 (1.1Mo)
	NF App Domestic-NF012_1947 (0.64Mo)
	OC / CB-FR_705591/A3 (0.73Mo)
	OC / CB-630164B/A1 (0.56Mo)
	OC / CB-FR_707077/M1 (0.43Mo)
	Decl. UE RED-A 4025 A (0.62Mo)
	NF App Domestic-NF012_2275/A2 (0.96Mo)
	NF App Domestic-NF012_4239 (0.53Mo)
	NF App Domestic-NF012_4512/M1 (0.91Mo)
	OC / CB-FR_719973 (0.41Mo)
	NF App Domestic-NF012_4072 (0.41Mo)
	NF App Domestic-NF012_4066 (0.52Mo)
	LGRP-01279-V01.02-EN.pdf PDF (0.7Mo)
	B.B.J-B12/005/24 (4.62Mo)
	OC / CB-HU-005022-M1 (0.7Mo)
	MEEI-UP 69267544 002 (1.23Mo)
	IRAM-DC-E-E100-003.1M2 (2.18Mo)