


Naziv PDF datoteke

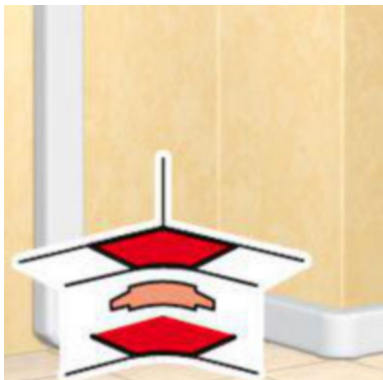

DLP LEGRAND

Variable internal angle for DLP universal trunking 2 compartments 50x150mm or 50x195mm

REF. 010606 | EAN KODA. 3245060106065

> [The product details page](#)

Značilnosti izdelka:

- Variable internal angle of 80 to 100 degrees
- Respect the protection index
- Improvement of aesthetics (covering of the cut)
- Delivered with junctions of partition
- Colour: white

Prednosti montaže:

- Clippes directly on the body of the trunking (with or without separation partition)

Prednosti uporabe:

- The internal angles ensure the continuity of the flexible cover on the angles, hence preventing cut of cover and being aesthetic

Dokumentacija

Tehnična dokumentacija

 F00885FR-05.pdf | PDF (1.98Mo)

 F00885EN-06.pdf | PDF (2.22Mo)

CAD & specifikacije načrtov / BIM

BIM-LEGRAND-TRUNKING-EXPORT-2024.rvt | RVT (14.36Mo)

BIM-LEGRAND-GOULOTTES-FRANCE-2024.rvt | RVT (13.17Mo)

BIM-LEGRAND-GOULOTTES-BELGIQUE-2024.rvt | RVT (23.93Mo)

Katalog & drugo

 ex223001_1073.pdf | PDF (0.11Mo)

 ex223001_1071.pdf | PDF (0.11Mo)

 ex223001_1074-1075.pdf | PDF (0.12Mo)

Pogodbe in certifikati

 NF Conduits-601796A | (0.42Mo)

 LGRP-01605-V02.01-FR.pdf | PDF (0.71Mo)

 LGRP-01605-V02.01-EN.pdf | PDF (0.75Mo)