


Naziv PDF datoteke

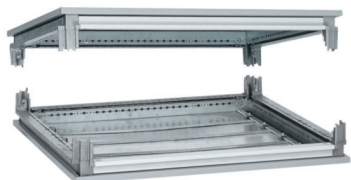

XL³ 4000 LEGRAND

Roof base for enclosure XL³ 4000 - depth 725 mm - width 975 mm

REF. 020505 | EAN KODA. 3245060205058

> [The product details page](#)

Značilnosti izdelka:

- Distribution enclosures XL³ 4000 - IP 30 - IK 07 - IP 55 - IK 08 with door and sealing kit for use when joining enclosures - Consist of the combination of a "roof - base" assembly, structural uprights, functional uprights, rear and side panels RAL 7035, plinths RAL 7004 - Height 2000 or 2200 mm. - Capacity 24 modules (enclosures width 725 or width 975 with internal cable sleeve), 36 modules (enclosures width 975) - Usable faceplate height 1800 mm (1700 mm only if using the pivoting support frame) or 2000 mm
- Enclosures and cable sleeves modular metal Roof - base for enclosure - Fitted with cable entry plates - Take the structural up Rights - Depth : 725 mm - Width external : 725 mm - Width usable : 600 mm

Dokumentacija

Tehnična dokumentacija

-  EXB22009_Flipbook_FR_(03_2022).pdf | PDF (6.2Mo)
-  F00254FR-05.pdf | PDF (0.67Mo)
-  EXB22010_Flipbook_EN_(03_2022).pdf | PDF (6.56Mo)
-  F00254EN-04.pdf | PDF (0.56Mo)
-  EXB15002_CA_XL3-4000-6300_EN.pdf | PDF (51.43Mo)
-  F0998K.pdf | PDF (1.8Mo)

CAD & specifikacije načrtov / BIM

-  Legrand_Armoire_XL³_6300-4000.rfa | RFA (0.54Mo)
-  Legrand_Distribution_enclosure_XL³_6300-4000.rfa | RFA (0.54Mo)

Katalog & drugo

-  ex223001_0380.pdf | PDF (0.14Mo)
-  ex223001_0383.pdf | PDF (0.08Mo)

Pogodbe in certifikati

-  LOVAG-IT 12.017 | (0.13Mo)
-  LOVAG-IT 12.019 | (0.59Mo)
-  LOVAG-IT 13.045 | (0.12Mo)