


Naziv PDF datoteke

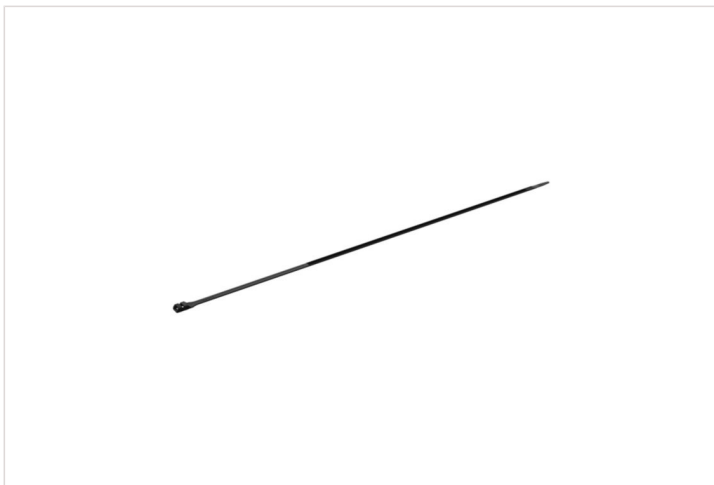

COLSON™ LEGRAND

Black cable tie Colson U.V. protected with internal teeth width 9mm and lenght 750 mm

REF. 031921 | EAN KODA. 3414971132283

> [The product details page](#)

Značilnosti izdelka:

- The temporary zone (with arrows) allows the clamps to be put on hold before final tightening. The manual snap - in area allows the insertion effort to be reduced before final tightening on the mechanical area with the tool ref 031996.mécanique avec l'outil ref 031996.
- Tear - off performance. Conformity to EN 62275
- Ergonomic heads with soft curves for more comfort during handling. Single head
- Resistance to UV, chemical agents, temperature, -Max. temperature in permanent use 85 °C - Minimum temperature in permanent use (clamp installed)-40 °C - Minimum installation temperature-30 °C".

Prednosti montaže:

- More comfort during installation.

Prednosti uporabe:

- A packaging with a reinforced bottom and pre-cuts to access the collars on the front or top of the box. The belt clip system allows the box to be used on site as a handyman.

Edinstvene značilnosti:

- Ergonomics of Colson collars. 3 application zones patented by Legrand. Practical and ingenious packaging with several pre-cuts and a belt attachment system to make the collars easier to use during installation.
- Colson clamps are also available in grey for perfect adaptation to IRL type tubes.

Dokumentacija

Tehnična dokumentacija

-  F00139FR-11.pdf | PDF (1.1Mo)
-  F00139EN-10.pdf | PDF (1.16Mo)
-  F002529FR-00.pdf | PDF (0.45Mo)
-  F002529EN-00.pdf | PDF (0.44Mo)

Pogodbe in certifikati

-  LGRP-00673-V01.01-EN.pdf | PDF (0.56Mo)