


Naziv PDF datoteke

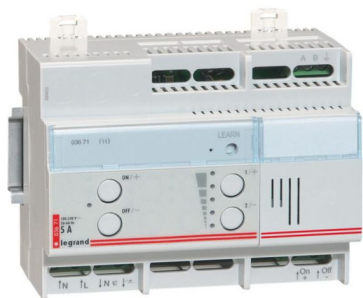

LEGRAND

Remote control dimmer via BUS line -
incandescent/halogen lamp - DIN 6 modules

REF. 003671 | EAN KODA. 3245060036713

> [The product details page](#)

Značilnosti izdelka:

- For incandescent and halogen lamps 230VAC, ELV halogen lamps with ferromagnetic or electronic transformers
- Load : 1000W (for 230VAC 50/60Hz)
- Mains voltage 100/240VAC - 50/60Hz
- DIN 6 modules
- Equipped with illuminated scale indicating the light level of controlled lamps

Prednosti montaže:

- Symmetrical rail mounting

Prednosti uporabe:

- Equipped with illuminated scale indicating the light level of controlled lamps

Edinstvene značilnosti:

- Equipped with illuminated scale indicating the light level of controlled lamps

Dokumentacija

Tehnična dokumentacija



0064JR3-03_EN.pdf | PDF (0.62Mo)



0064JR3-03_FR.pdf | PDF (0.62Mo)

CAD & specifikacije načrtov / BIM



003671.dwg | DWG (0.12Mo)

Katalog & drugo



ex223001_0108.pdf | PDF (0.08Mo)