


Naziv PDF datoteke

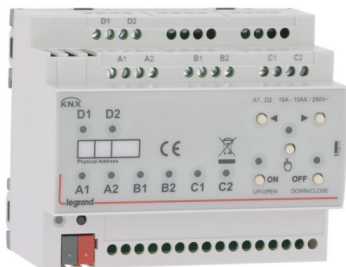

LEGRAND

KNX controller multi-applications din 8 outputs

REF. 002672 | EAN KODA. 3414972052306

> [The product details page](#)

Značilnosti izdelka:

- 8 outputs - 16A - 250 VAC 50/60 Hz - 4000 VA max
- DIN 10 modules
- Power supply from KNX bus (= 10mA)

Priporočila / omejitve

- Configuration through ETS tool from KNX association

Prednosti montaže:

- Connected with the BUS/KNX cable

Prednosti uporabe:

- All in one product for different room layouts such as apartments, hotel rooms, hospitals and residences: switching lighting, switching loads, controlling AC/DC blinds, controlling fan coils (2 & 3 point valve)

Edinstvene značilnosti:

- Grouped 4 outputs as 2 independent output channels configurable for different modes of operation: switching output x4, AC blind x2, DC blind x1, 2 Point valve x2, 3 point valve x1
- Suitable for switching resistive, capacitive and inductive loads as well as fluorescent lamp following several functions: staircase, external logic, internal logic, priority, threshold, operating hour, sweep

Dokumentacija

Tehnična dokumentacija

- LE12358AD.pdf | PDF (0.62Mo)
- S000114123EN_4.pdf | PDF (4.97Mo)
- S000114123FR_4.pdf | PDF (4.85Mo)

Pogodbe in certifikati

- KNX EIB-11/16826/20 | (0.79Mo)

Katalog & drugo

- ex223001_0896.pdf | PDF (0.07Mo)

Oznaka besedila

- USE CASE_ L.NOW Thermo. 2P ON_OFF.zip | ZIP (1.61Mo)
- USE CASE_ L.NOW Thermo. 2P ON_OFF 3pts.zip | ZIP (1.71Mo)
- LOG_RA00198AA_002672-V01.01.zip | ZIP (0.16Mo)

	USE CASE_ L.NOW Thermo. 4P ON_OFF 3pts.zip ZIP (1.91Mo)
	USE CASE_002890_S000125340.zip ZIP (2.06Mo)
	USE CASE_002890_S000125336.zip ZIP (2.05Mo)
	USE CASE_002890_S000125337.zip ZIP (2.1Mo)
	USE CASE_002890_S000125338.zip ZIP (2.12Mo)
	USE CASE_002890_S000125339.zip ZIP (2.04Mo)
	USE CASE_002890_S000125341.zip ZIP (2.04Mo)
	USE_CASE_ Malia _Thermo. 2P_ON_OFF_3pts.zip ZIP (1.95Mo)
	USE CASE_ L.NOW Thermo. 4P ON_OFF.zip ZIP (1.86Mo)