


# Naziv PDF datoteke

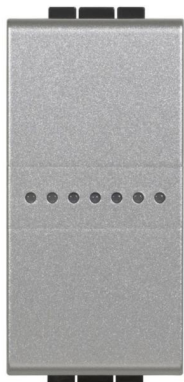

## LIVING LIGHT BTICINO

Connected switch with neutral (with dimmer option)  
150W Living Light with Netatmo

REF. BT-NT4411C | EAN KODA. 8005543668320

> [The product details page](#)

## Značilnosti izdelka:

- Max load power : 150W under 230V~, all loads leds included
- Compatible with traditional or dimmable bulbs, including LED. Dimmer activatable via Home + Control App
- LED indicator with locator function which can be activated in the app
- Equipped with an auxiliary entry for a mechanical push button
- Tech

## Priporočila / omejitve

- To connect your connected switch with neutral (with dimmer option), it is necessary to purchase and install a Living Light with Netatmo connected starter pack beforehand. To control it as a 2 way switch, it is necessary to associate one or more Living Light with Netatmo wireless commands to it and / or wire it with a mechanical push button.

## Prednosti montaže:

- The Living Light with Netatmo connected switch with neutral (with dimmer option) is easily installed in place of an existing switch and requires a standard depth flush mounting box (40mm). Compatible with claw frames. Does not require the installation of a bleeder

## Prednosti uporabe:

- Control your lights with your voice using a vocal assistant

## Edinstvene značilnosti:

- Perfect aesthetic integration with the installed wiring devices
- Using ON/OFF mode, compatible with all type of loads, dimmable or not
- Very easy to use with multi-zone ergonomics

## Dokumentacija

### Tehnična dokumentacija



IDP000389\_01-EN.pdf | PDF (0.88Mo)



LE12015AB.pdf | PDF (0.96Mo)

### Pogodbe in certifikati



Decl. UE RED-A 3957 B | (0.09Mo)



OC / CB-DE 2-0310068 | (0.66Mo)